


Product datasheet

Specifications

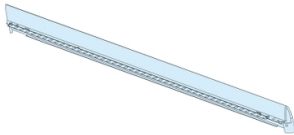

COMBINATION PROFILE 27M PRISMA G IP30

01030

! Discontinued on: 9 Aug 2023

EAN Code: 3303430010302

! Discontinued

Main

Range	Prisma
Range Of Product	Prisma G
Product Or Component Type	Central upright
Accessory / Separate Part Category	Coupling accessory Spare part
Range Compatibility	Prisma Prisma G enclosure
Ip Degree Of Protection	IP30
Accessory / Separate Part Destination	For side by side framework combination

Complementary

Installation Description	Floor-standing enclosure - width 600 mm Floor-standing enclosure - width 300 mm Floor-standing enclosure - width 850 mm
Number Of Vertical Modules [50 Mm]	27
Mounting Location	Side by side
Quantity Per Set	Set of 1
Height	1380 mm
Net Weight	2.4 kg
Surface Finish	Smooth Matt
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	8.000 cm
Package 1 Width	21.000 cm
Package 1 Length	138.500 cm
Package 1 Weight	2.400 kg
Unit Type Of Package 2	PAL
Number Of Units In Package 2	36

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Package 2 Height	75.000 cm
Package 2 Width	200.000 cm
Package 2 Length	120.000 cm
Package 2 Weight	86.400 kg

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability



Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Halogen Free Plastic Parts Product	

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information