




Price* : 30.18 GBP

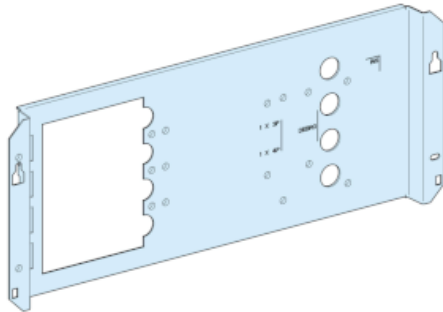

Main

Range	Prisma
Range compatibility	Prisma G
Product or component type	Mounting plate
Accessory / separate part category	Installation accessory
Installed device	Compact: fixed INS250 - control: lateral handle - vertical installation Compact: fixed INV250 - control: lateral handle - vertical installation Compact: fixed NSX100...160 without earth leakage protection - control: motor mechanism - horizontal installation Compact: plug-in NSX100...160 without earth leakage protection - control: toggle - horizontal installation Compact: fixed NSX250 without earth leakage protection - control: motor mechanism - horizontal installation Compact: plug-in NSX250 without earth leakage protection - control: toggle - horizontal installation
Poles description	1 x 3P: fixed NSX100...160 horizontal installation 1 x 4P: fixed NSX100...160 horizontal installation 1 x 3P: fixed NSX250 horizontal installation 1 x 4P: fixed NSX250 horizontal installation 1 x 3P: fixed INS250 vertical installation 1 x 4P: fixed INS250 vertical installation 1 x 3P: fixed INV250 vertical installation 1 x 4P: fixed INV250 vertical installation 1 x 3P: plug-in NSX100...160 horizontal installation 1 x 4P: plug-in NSX100...160 horizontal installation 1 x 3P: plug-in NSX250 horizontal installation 1 x 4P: plug-in NSX250 horizontal installation

Complementary

Installation description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Floor-standing enclosure + duct - width 600 + 300 mm Wall-mounted enclosure + duct - width 600 + 300 mm
Number of vertical modules [50 mm]	4 module(s): NSX100...160 without earth leakage protection , direct with long terminal shield in 600 + 300 mm Widefloor-standing enclosure + duct (cable coming from top or bottom of enclosure)

4 module(s): NSX100...160 without earth leakage protection , direct with long terminal shield in 600 + 300 mm Widewall-mounted enclosure + duct (cable coming from top or bottom of enclosure)
 4 module(s): NSX250 without earth leakage protection , direct with long terminal shield in 600 + 300 mm Widefloor-standing enclosure + duct (cable coming from top or bottom of enclosure)
 4 module(s): NSX250 without earth leakage protection , direct with long terminal shield in 600 + 300 mm Widewall-mounted enclosure + duct (cable coming from top or bottom of enclosure)
 8 module(s): INS250, direct with long terminal shield in 600 mm Widefloor-standing enclosure (cable coming from top or bottom of enclosure)
 8 module(s): INS250, direct with long terminal shield in 600 mm Widewall-mounted enclosure (cable coming from top or bottom of enclosure)
 8 module(s): INV250, direct with long terminal shield in 600 mm Widefloor-standing enclosure (cable coming from top or bottom of enclosure)
 8 module(s): INV250, direct with long terminal shield in 600 mm Widewall-mounted enclosure (cable coming from top or bottom of enclosure)

Condition of using cable tie	Need additional plate (2M high) when installation of device is in horizontal Need additional plate (1M high) when installation of device is in vertical
Height	150 mm
Product weight	0.96 kg
Surface finish	Matt Smooth
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)

Environment

Standards	IEC 61439-2
Product certifications	ASEFA

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	Download RoHS China Declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Contractual warranty

Warranty	18 months
----------	-----------