


Product datasheet

Specifications

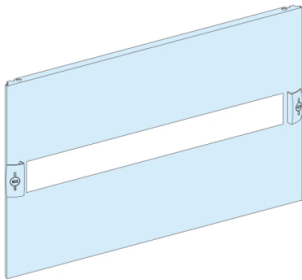

MODULAR FRONT PLATE WIDTH 600/650 5M

03205

! Discontinued on: 9 Aug 2023

EAN Code: 3303430032052

! Discontinued

Main

Range	Prisma
Range Of Product	Prisma G Prisma P
Product Or Component Type	Front plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma G enclosure Prisma Prisma P cubicle
Type Of Front Plate	Modular Cut-out
Installed Device	ComPact: fixed INS100 - control: direct front rotary handle - vertical installation ComPact: fixed INS125 - control: direct front rotary handle - vertical installation ComPact: fixed INS160 - control: direct front rotary handle - vertical installation Acti 9: fixed C120 without earth leakage protection - control: toggle TeSys: fixed GV3 Acti 9: fixed iC120 without earth leakage protection - control: toggle Multi9: fixed NG125 without earth leakage protection - control: toggle Multi9: fixed NG125 NA - control: toggle ComPact: fixed NG160 without earth leakage protection - control: toggle ComPact: fixed NG160 NA without earth leakage protection - control: toggle TeSys: fixed TeSys U - horizontal installation Acti 9: fixed C120 with earth leakage protection - control: toggle Acti 9: fixed iC120 with earth leakage protection - control: toggle Multi9: fixed NG125 with earth leakage protection - control: toggle ComPact: fixed NG160 with earth leakage protection - control: toggle ComPact: fixed NSXm without earth leakage protection - control: toggle - vertical installation ComPact: fixed NSXm with earth leakage protection - control: toggle - vertical installation

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Poles Description	1 x 3P: modular rail support: INS100 vertical installation 1 x 4P: modular rail support: INS100 vertical installation 1 x 3P: modular rail support: INS125 vertical installation 1 x 4P: modular rail support: INS125 vertical installation 1 x 3P: modular rail support: INS160 vertical installation 1 x 4P: modular rail support: INS160 vertical installation 1 x 3P: modular rail support: C120 1 x 4P: modular rail support: C120 7 x 3P: modular rail support: GV3 1 x 3P: modular rail support: iC120 1 x 4P: modular rail support: iC120 1 x 3P: modular rail support: NG125 1 x 4P: modular rail support: NG125 1 x 3P: modular rail support: NG125 NA 1 x 4P: modular rail support: NG125 NA 1 x 3P: modular rail support: NG160 1 x 4P: modular rail support: NG160 1 x 3P: modular rail support: NG160 NA 1 x 4P: modular rail support: NG160 NA 9 x 3P: modular rail support: TeSys U horizontal installation 1 x 3P or 4P: modular rail support: NSXm vertical installation 5 x 3P: mounting plate support: NSXm vertical installation 4 x 4P: mounting plate support: NSXm vertical installation 4 x 3P or 4P: mounting plate support: NSXm vertical installation
Operating Position	Vertical

Complementary

Enclosure/Cubicle Description	Floor-standing enclosure - width 600 mm Wall-mounted enclosure - width 600 mm Cubicle - width 650 mm depth 400 mm Pack enclosure - width 555 mm
Connection Position	Direct connection
9 Mm Pitches	48
Number Of 18 Mm Modules Per Row	24
Number Of Vertical Modules [50 Mm]	5
Standards	IEC 61439-2 IEC 61439-1
Product Certifications	ASEFA
Material	Steel
Surface Finish	Smooth Matt
Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9001)
Height	250 mm
Width	500 mm
Net Weight	0.92 kg
Quantity Per Set	Set of 1

Functional Unit	600 mm Prisma G floor-standing enclosure Acti 9 C120 without fixed toggle 3P 1 direct 5
	600 mm Prisma G wall-mounted enclosure Acti 9 C120 without fixed toggle 3P 1 direct 5
	600 mm Prisma G floor-standing enclosure Acti 9 C120 without fixed toggle 4P 1 direct 5
	600 mm Prisma G wall-mounted enclosure Acti 9 C120 without fixed toggle 4P 1 direct 5
	650 mm 400 mm Prisma P cubicle Acti 9 C120 without fixed toggle 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle Acti 9 C120 without fixed toggle 4P 1 direct 5
	600 mm Prisma G floor-standing enclosure TeSys GV3 fixed 3P 7 direct 5
	600 mm Prisma G wall-mounted enclosure TeSys GV3 fixed 3P 7 direct 5
	650 mm 400 mm Prisma P cubicle TeSys GV3 fixed 3P 7 direct 5
	600 mm Prisma G floor-standing enclosure Acti 9 iC120 without fixed toggle 3P 1 direct 5
	600 mm Prisma G wall-mounted enclosure Acti 9 iC120 without fixed toggle 3P 1 direct 5
	600 mm Prisma G floor-standing enclosure Acti 9 iC120 without fixed toggle 4P 1 direct 5
	600 mm Prisma G wall-mounted enclosure Acti 9 iC120 without fixed toggle 4P 1 direct 5
	650 mm 400 mm Prisma P cubicle Acti 9 iC120 without fixed toggle 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle Acti 9 iC120 without fixed toggle 4P 1 direct 5
	600 mm Prisma G floor-standing enclosure ComPact INS100 fixed direct front rotary handle vertical 3P 1 direct 5
	600 mm Prisma G wall-mounted enclosure ComPact INS100 fixed direct front rotary handle vertical 3P 1 direct 5
	600 mm Prisma G floor-standing enclosure ComPact INS100 fixed direct front rotary handle vertical 4P 1 direct 5
	600 mm Prisma G wall-mounted enclosure ComPact INS100 fixed direct front rotary handle vertical 4P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact INS100 fixed direct front rotary handle vertical 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact INS100 fixed direct front rotary handle vertical 4P 1 direct 5
	600 mm Prisma G floor-standing enclosure ComPact INS125 fixed direct front rotary handle vertical 3P 1 direct 5
	600 mm Prisma G wall-mounted enclosure ComPact INS125 fixed direct front rotary handle vertical 3P 1 direct 5
	600 mm Prisma G floor-standing enclosure ComPact INS125 fixed direct front rotary handle vertical 4P 1 direct 5
	600 mm Prisma G wall-mounted enclosure ComPact INS125 fixed direct front rotary handle vertical 4P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact INS125 fixed direct front rotary handle vertical 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact INS125 fixed direct front rotary handle vertical 4P 1 direct 5
	600 mm Prisma G floor-standing enclosure ComPact INS160 fixed direct front rotary handle vertical 3P 1 direct 5
	600 mm Prisma G wall-mounted enclosure ComPact INS160 fixed direct front rotary handle vertical 3P 1 direct 5
	600 mm Prisma G floor-standing enclosure ComPact INS160 fixed direct front rotary handle vertical 4P 1 direct 5
	600 mm Prisma G wall-mounted enclosure ComPact INS160 fixed direct front rotary handle vertical 4P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact INS160 fixed direct front rotary handle vertical 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle ComPact INS160 fixed direct front rotary handle vertical 4P 1 direct 5
	600 mm Prisma G floor-standing enclosure Multi9 NG125 without fixed toggle 3P 1 direct 5
	600 mm Prisma G wall-mounted enclosure Multi9 NG125 without fixed toggle 3P 1 direct 5
	600 mm Prisma G floor-standing enclosure Multi9 NG125 without fixed toggle 4P 1 direct 5
	600 mm Prisma G wall-mounted enclosure Multi9 NG125 without fixed toggle 4P 1 direct 5
	650 mm 400 mm Prisma P cubicle Multi9 NG125 without fixed toggle 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle Multi9 NG125 without fixed toggle 4P 1 direct 5
	600 mm Prisma G floor-standing enclosure Multi9 NG125 NA fixed toggle 3P 1 direct 5
	600 mm Prisma G wall-mounted enclosure Multi9 NG125 NA fixed toggle 3P 1 direct 5
	600 mm Prisma G floor-standing enclosure Multi9 NG125 NA fixed toggle 4P 1 direct 5
	600 mm Prisma G wall-mounted enclosure Multi9 NG125 NA fixed toggle 4P 1 direct 5
	650 mm 400 mm Prisma P cubicle Multi9 NG125 NA fixed toggle 3P 1 direct 5
	650 mm 400 mm Prisma P cubicle Multi9 NG125 NA fixed toggle 4P 1 direct 5
	600 mm Prisma G floor-standing enclosure ComPact NG160 without fixed toggle 3P

1 direct 5
600 mm Prisma G wall-mounted enclosure ComPact NG160 without fixed toggle 3P
1 direct 5
600 mm Prisma G floor-standing enclosure ComPact NG160 without fixed toggle 4P
1 direct 5
600 mm Prisma G wall-mounted enclosure ComPact NG160 without fixed toggle 4P
1 direct 5
650 mm 400 mm Prisma P cubicle ComPact NG160 without fixed toggle 3P 1 direct
5
650 mm 400 mm Prisma P cubicle ComPact NG160 without fixed toggle 4P 1 direct
5
600 mm Prisma G floor-standing enclosure ComPact NG160 NA without fixed toggle
3P 1 direct 5
600 mm Prisma G wall-mounted enclosure ComPact NG160 NA without fixed toggle
3P 1 direct 5
600 mm Prisma G floor-standing enclosure ComPact NG160 NA without fixed toggle
4P 1 direct 5
600 mm Prisma G wall-mounted enclosure ComPact NG160 NA without fixed toggle
4P 1 direct 5
650 mm 400 mm Prisma P cubicle ComPact NG160 NA without fixed toggle 3P 1
direct 5
650 mm 400 mm Prisma P cubicle ComPact NG160 NA without fixed toggle 4P 1
direct 5
650 mm 400 mm Prisma P cubicle TeSys TeSys U fixed horizontal 3P 9 direct 5
600 mm Prisma G floor-standing enclosure Acti 9 C120 with fixed toggle 3P 1 direct
5
600 mm Prisma G wall-mounted enclosure Acti 9 C120 with fixed toggle 3P 1 direct 5
600 mm Prisma G floor-standing enclosure Acti 9 C120 with fixed toggle 4P 1 direct
5
600 mm Prisma G wall-mounted enclosure Acti 9 C120 with fixed toggle 4P 1 direct 5
650 mm 400 mm Prisma P cubicle Acti 9 C120 with fixed toggle 3P 1 direct 5
650 mm 400 mm Prisma P cubicle Acti 9 C120 with fixed toggle 4P 1 direct 5
600 mm Prisma G floor-standing enclosure Acti 9 iC120 with fixed toggle 3P 1 direct
5
600 mm Prisma G wall-mounted enclosure Acti 9 iC120 with fixed toggle 3P 1 direct
5
600 mm Prisma G floor-standing enclosure Acti 9 iC120 with fixed toggle 4P 1 direct
5
600 mm Prisma G wall-mounted enclosure Acti 9 iC120 with fixed toggle 4P 1 direct
5
650 mm 400 mm Prisma P cubicle Acti 9 iC120 with fixed toggle 3P 1 direct 5
650 mm 400 mm Prisma P cubicle Acti 9 iC120 with fixed toggle 4P 1 direct 5
600 mm Prisma G floor-standing enclosure Multi9 NG125 with fixed toggle 3P 1
direct 5
600 mm Prisma G wall-mounted enclosure Multi9 NG125 with fixed toggle 3P 1
direct 5
600 mm Prisma G floor-standing enclosure Multi9 NG125 with fixed toggle 4P 1
direct 5
600 mm Prisma G wall-mounted enclosure Multi9 NG125 with fixed toggle 4P 1
direct 5
650 mm 400 mm Prisma P cubicle Multi9 NG125 with fixed toggle 3P 1 direct 5
650 mm 400 mm Prisma P cubicle Multi9 NG125 with fixed toggle 4P 1 direct 5
600 mm Prisma G floor-standing enclosure ComPact NG160 with fixed toggle 3P 1
direct 5
600 mm Prisma G wall-mounted enclosure ComPact NG160 with fixed toggle 3P 1
direct 5
600 mm Prisma G floor-standing enclosure ComPact NG160 with fixed toggle 4P 1
direct 5
600 mm Prisma G wall-mounted enclosure ComPact NG160 with fixed toggle 4P 1
direct 5
650 mm 400 mm Prisma P cubicle ComPact NG160 with fixed toggle 3P 1 direct 5
650 mm 400 mm Prisma P cubicle ComPact NG160 with fixed toggle 4P 1 direct 5
600 mm Prisma G floor-standing enclosure ComPact NSXm without fixed toggle
vertical 3P or 4P 1 direct 7
600 mm Prisma G wall-mounted enclosure ComPact NSXm without fixed toggle
vertical 3P or 4P 1 direct 7
600 mm Prisma G floor-standing enclosure ComPact NSXm without fixed toggle
vertical 3P or 4P 1 connection block 7
600 mm Prisma G wall-mounted enclosure ComPact NSXm without fixed toggle
vertical 3P or 4P 1 connection block 7
650 mm 400 mm Prisma P cubicle ComPact NSXm without fixed toggle vertical 3P or
4P 1 direct 8
650 mm 400 mm Prisma P cubicle ComPact NSXm without fixed toggle vertical 3P 5
direct 8
650 mm 400 mm Prisma P cubicle ComPact NSXm without fixed toggle vertical 4P 4
direct 8
600 mm Prisma G floor-standing enclosure ComPact NSXm with fixed toggle vertical
3P or 4P 1 direct 7
600 mm Prisma G wall-mounted enclosure ComPact NSXm with fixed toggle vertical
3P or 4P 1 direct 7

600 mm Prisma G floor-standing enclosure ComPact NSXm with fixed toggle vertical
3P or 4P 1 connection block 7
600 mm Prisma G wall-mounted enclosure ComPact NSXm with fixed toggle vertical
3P or 4P 1 connection block 7
650 mm 400 mm Prisma P cubicle ComPact NSXm with fixed toggle vertical 3P or
4P 1 direct 8
650 mm 400 mm Prisma P cubicle ComPact NSXm with fixed toggle vertical 3P or
4P 4 direct 8

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	4.000 cm
Package 1 Width	26.000 cm
Package 1 Length	51.500 cm
Package 1 Weight	900.000 g
Unit Type Of Package 2	CAR
Number Of Units In Package 2	10
Package 2 Height	17.000 cm
Package 2 Width	27.700 cm
Package 2 Length	52.600 cm
Package 2 Weight	9.400 kg
Unit Type Of Package 3	P12
Number Of Units In Package 3	270
Package 3 Height	96.000 cm
Package 3 Width	80.000 cm
Package 3 Length	120.000 cm
Package 3 Weight	254.880 kg

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
✓	Halogen Free Plastic Parts Product	

Certifications & Standards

Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile