


Product datasheet

Specifications

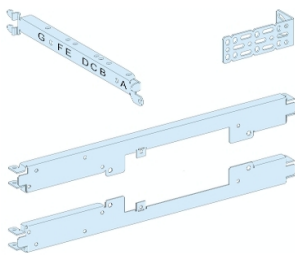

M.PL.HZ.NS250 C/O MOT.OR UA/BA

03417

Discontinued on: 5 Apr 2023

EAN Code: 3303430034179

Discontinued

Main

Range	Prisma
Range Of Product	Prisma P
Product Or Component Type	Mounting plate
Accessory / Separate Part Category	Installation accessory
Range Compatibility	Prisma Prisma P cubicle
Installation Description	Cubicle - width 650 mm depth 400 mm Cubicle - width 650 mm depth 600 mm
Installed Device	Source changeover: fixed BA controller - horizontal installation Source changeover: fixed NSX100...250 source changeover - control: remote control - horizontal installation Source changeover: fixed UA controller - horizontal installation
Poles Description	2 x 3P: fixed NSX100...250 source changeover horizontal installation 2 x 4P: fixed NSX100...250 source changeover horizontal installation
Number Of Vertical Modules [50 Mm]	4 module(s): BA controller, direct in 650 mm Widecubicle 8 module(s): NSX100...250 source changeover, direct in 650 mm Widecubicle 4 module(s): UA controller, direct in 650 mm Widecubicle
Standards	IEC 61439-2
Product Certifications	ASEFA

Complementary

Protective Treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Surface Finish	Matt Smooth
Colour	White (RAL 9001)
Width	650 mm
Height	200 mm
Net Weight	3 kg
Functional Unit	650 mm 600 mm Prisma P cubicle source changeover BA controller fixed horizontal 1 direct 4 12.5 mm 650 mm 400 mm Prisma P cubicle source changeover NSX100...250 source changeover fixed remote control horizontal 3P 2 direct 8 12.5 mm 650 mm 400 mm Prisma P cubicle source changeover NSX100...250 source changeover fixed remote control horizontal 4P 2 direct 8 12.5 mm 650 mm 600 mm Prisma P cubicle source changeover UA controller fixed horizontal 1 direct 4 12.5 mm

Packing Units

Unit Type Of Package 1	PCE
------------------------	-----

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Number Of Units In Package 1	1
Package 1 Height	4 cm
Package 1 Width	11 cm
Package 1 Length	57 cm
Package 1 Weight	2.9 kg

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

✓	Mercury Free	
✓	RoHS Exemption Information	Yes
✓	Halogen Free Plastic Parts Product	

Certifications & Standards

Eu RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information