


GK1CF

fuse holder - GK1 - 3 poles - 20 A - for fuse NFC
8.5 x 31.5 mm

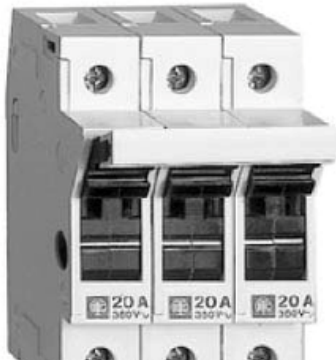

ⓘ Discontinued

GK1CF has not been replaced. Please contact your customer care centre for more information.

Main

Range	TeSys
Product name	TeSys GK1
Device short name	GK1 C
Fuse size	8.5 x 31.5 mm
Product or component type	Fuse holder
Poles description	3P
Network type	AC DC
[I _{th}] conventional free air thermal current	10 A 40 °C with aM cartridge fuses 20 A 40 °C with gG cartridge fuses 20 A 40 °C with tubular links
Quantity per set	Set of 4

Complementary

Network frequency	50/60 Hz
Control type	Toggle
Mounting support	Rail
[U _i] rated insulation voltage	480 V
[I _{pk}] rated peak withstand current	8 kA with tubular links conforming to IEC 60269-1
Connections - terminals	Screw terminals 1 cable(s) 10 mm ² flexible without cable end Screw terminals 1 cable(s) 10 mm ² solid without cable end Screw terminals 2 cable(s) 6 mm ² flexible without cable end Screw terminals 2 cable(s) 6 mm ² solid without cable end
Tightening torque	1.2 N.m - on screw terminals
Operating position	+/- 23°
Height	81 mm
Width	52.5 mm
Depth	71.5 mm
Net weight	0.213 kg

Environment

Standards	IEC 60947-3
Protective treatment	TC

Ambient air temperature for operation	-50...70 °C
---------------------------------------	-------------

Contractual warranty

Warranty	18 months
----------	-----------
