


# Product datasheet

Specifications

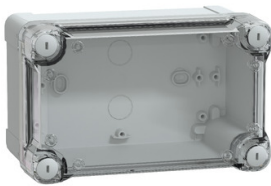

PC box IP66 IK08 RAL7035  
Int.H175W105D100  
Ext.H192W121D105 Transp.cover  
H40

Local distributor code:  
387531959

NSYTBP191210HT

EAN Code: 3606480165818

## Main

Range	Thalassa
Product Name	Thalassa TBP
Device Application	Multi-purpose
Category	Industrial box
Height	192 mm
Width	121 mm
Depth	105 mm
Internal Height	175 mm
Internal Width	105 mm
Internal Depth	100 mm
Enclosure Mounting	Wall mounted
Device Composition	1 body 1 cover 4 cover screw
Quantity Per Set	Set of 2
Body Type	One piece moulded
Type Of Front Cover	High transparent cover
Cover Fixing	Plastic screws
Lock Type	Captive screw flat outside sealed area
Removable Parts	Cover by captive screws

## Complementary

Material	Polycarbonate
Colour	Grey (RAL 7035) Transparent
Standards	IEC 62208 UL 508 A
Product Certifications	TÜV UL
Electrical Insulation Class	Class II
Mounting Location	Outdoor (with canopy or shelter and anticondensation valve)
Net Weight	0.45 kg

## Environment

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Ip Degree Of Protection	IP66 conforming to NEMA 4.4X
Ik Degree Of Protection	IK08 conforming to IEC 62262
Fire Resistance	960 °C
Ambient Air Temperature For Storage	-15...60 °C
Operating Temperature	-25...80 °C

## Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	10.5 cm
Package 1 Width	12.1 cm
Package 1 Length	19.2 cm
Package 1 Weight	489 g
Unit Type Of Package 2	PAM
Number Of Units In Package 2	550
Package 2 Height	120 cm
Package 2 Width	100 cm
Package 2 Length	215 cm
Package 2 Weight	306 kg

## Contractual warranty

Warranty	18 months
----------	-----------

Sustainability



**Green Premium™ label** is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency   RoHS/REACH

## Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes

## Certifications & Standards

Reach Regulation	<a href="#">REACH Declaration</a>
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
China Rohs Regulation	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	<a href="#">End of Life Information</a>