

# Product datasheet

Specifications



braking resistor - 27 ohm - 200 W -  
cable 2 m - IP65

VW3A7603R20

⚠ End-of-service on: 24 Nov 2021

EAN Code: 3389119207157

⚠ Discontinued

## Main

Range Of Product	Lexium Altivar
Range Compatibility	Lexium 05 Lexium 28 Lexium 32 Lexium 15 Lexium 52 Lexium 32i Easy Lexium 16
Product Compatibility	Motion servo drive LXM16D at 0.75 kW, 200...230 V, single phase Motion servo drive LXM16D at 1 kW, 200...230 V, single phase Motion servo drive LXM16D at 1.5 kW, 200...230 V, single phase
Product Or Component Type	Braking resistor
Ohmic Value	27 Ohm

## Complementary

Energy Peak	4300 J at 480 V 4900 J at 400 V 7400 J at 230 V 9700 J at 115 V
Continuous Power	200 W
Protection Type	Thermal protection via the servo drive
Net Weight	1.08 kg
Cable Length	2 m

## Environment

Ip Degree Of Protection	IP65
Ambient Air Temperature For Storage	-25...85 °C
Ambient Air Temperature For Operation	0...50 °C

## Contractual warranty


Warranty	18 months
----------	-----------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Dimensions Drawings

Braking Resistor

Dimensions

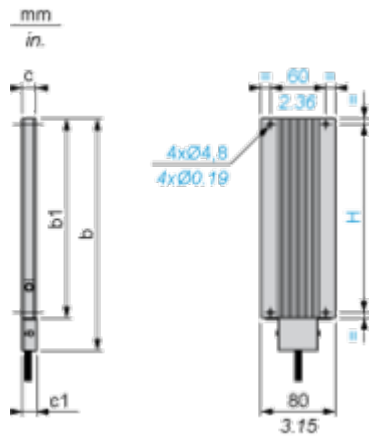

Dimensions in mm

b	b1	c	c1	H
251	216	15	15.5	204

Dimensions in in.

b	b1	c	c1	H
9.88	8.50	0.59	0.61	8.03